


Outdoor Unibody Cabinet

Data Solutions

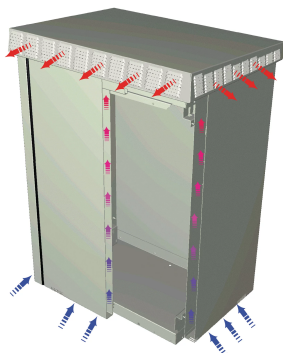

Telecom and Railway applications require sophisticated electronics in outdoor setups. nVent SCHROFF Outdoor cabinets shield such electronic components from extreme weather and vandalism, ensuring operational continuity.

CERTIFICERINGER



FUNKTIONER

Double-walled, Al

IP 55

One-piece inner case with removable outer cladding

Heat dissipation through natural convection, max. 5 W/K (11249-003) / 6 W/K (11249-005)

SPECIFIKATIONER

Materiale: Aluminium

Table 1/3

Katalognummer	Product Type	Produktfamilie	Rack Height	Højde	Bredde	Dybde
11249-005	Outdoor Cabinet	Unibody	20U	1100mm	700mm	500mm

Katalognummer	Product Type	Produktfamilie	Rack Height	Højde	Bredde	Dybde
11249-003	Outdoor Cabinet	Unibody	16U	930mm	700mm	500mm

Table 2/3

Katalognummer	Wall Type	Door Type	Access	Cooling	EMC Shielding	Complies With
11249-005	Double Walled	Single Door	Front	Natural Convection	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160
11249-003	Double Walled	Single Door	Front	Natural Convection	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160

Table 3/3

Katalognummer	Pakke mængde	Finish
11249-005	1	Struktur Pulvermaling
11249-003	1	Struktur Pulvermaling

YDERLIGERE PRODUKTOPLYSNINGER

Please order panel/slide mounts separately.

Further base/plinth heights on request.

Please order wall-mounting assembly kit separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugældiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE