

Telecom Main Grounding Busbar

Data Solutions



CERTIFICATION



FUNCTION

Meets TIA-607-C and TIA-607-D and conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

SPECIFICATION

Thickness (T): 6.35mm
Width (W): 101.6mm
Material: Copper

Table 1/2


Katalognummer	Tin Plating	Length 1 (L1)	Length 2 (L2)	Hole Size 1 Number of Pairs	Hole Size 2 Number of Pairs	A
---------------	-------------	---------------	---------------	-----------------------------------	-----------------------------------	---

TMGBA12L15P	No	305mm	229mm	15	3	25.4mm
TMGBA12L15PT	Yes	305mm	229mm	15	3	25.4mm
TMGBA20L27P	No	508mm	229mm	27	3	25.4mm
TMGBA24L33PT	Yes	610mm	457mm	33	5	25.4mm

Table 2/2

Katalognummer	B	C	D
TMGBA12L15P	28.6mm	15.9mm	15.9mm
TMGBA12L15PT	28.6mm	15.9mm	15.9mm
TMGBA20L27P	28.6mm	15.9mm	15.9mm
TMGBA24L33PT	28.6mm	15.9mm	15.9mm

DIAGRAMS

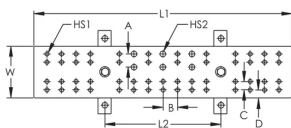

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE