

TR Four Pole Distribution Block, 400 A

Data Solutions



CERTIFICERINGER



FUNKTIONER

Easily fixes onto DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER


Katalognummer	TR-400A
Artikelnummer	562010
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass

Katalognummer	TR-400A
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	34kA
Short Term Withstand Current (Icw) 1s	28kA
Line Side Number of Connections	1
Load Side Number of Connections	8
Hole Size (HS)	10mm
Thread Size (TS)	M6
Dybde (D)	140mm
Height (H)	240mm
Width (W)	300mm
Unit Weight	2.83kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

DIAGRAMS

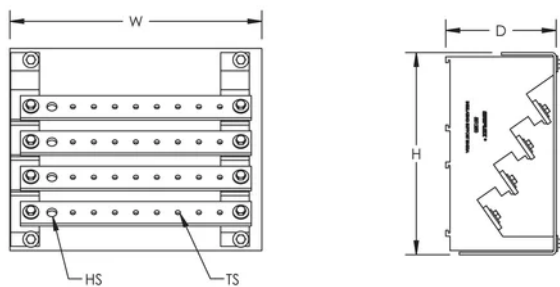

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE