


Varistar CP Double Steel Door, Perforated, 3-Point Locking

Data Solutions

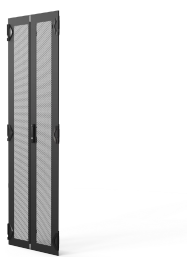

Perforated Varistar CP steel double door with 3-point locking for applications with IP 20 protection

FUNKTIONER

Double perforated steel door with 3 point locking for IP 20 protection class

Lever handle with key insert (2 keys)

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with lever handle 24630003 and DIN profile half cylinder with keys or push button

SPECIFIKATIONER

Locking Type: 3-Point Locking

Product Type: Cabinet Door

Beskyttelsesgrad: IP20

Materiale: Stål

Table 1/2

Katalognummer	Rack Height	Højde	Bredde	Pakke mængde	Farve	Farvekode
21630-020	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-021	47U	2200mm	600mm	1	Black Grey	RAL 7021

Katalognummer	Rack Height	Højde	Bredde	Pakke mængde	Farve	Farvekode
21630-022	52U	2450mm	600mm	1	Black Grey	RAL 7021
21630-027	42U	2000mm	800mm	1	Black Grey	RAL 7021
21630-028	47U	2200mm	800mm	1	Black Grey	RAL 7021
21630-029	52U	2450mm	800mm	1	Black Grey	RAL 7021
21630-448	24U	1200mm	600mm	1	Black Grey	RAL 7021
21630-449	24U	1200mm	800mm	1	Black Grey	RAL 7021
21630-450	29U	1400mm	600mm	1	Black Grey	RAL 7021
21630-451	29U	1400mm	800mm	1	Black Grey	RAL 7021
21630-452	33U	1600mm	600mm	1	Black Grey	RAL 7021
21630-453	33U	1600mm	800mm	1	Black Grey	RAL 7021
21630-454	38U	1800mm	600mm	1	Black Grey	RAL 7021
21630-455	38U	1800mm	800mm	1	Black Grey	RAL 7021

Table 2/2				
Katalognummer	Complies With	Finish	Type	Works With
21630-020	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-021	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-022	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-027	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-028	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP

Katalognummer	Complies With	Finish	Type	Works With
21630-029	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-448	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-449	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-450	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-451	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-452	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-453	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-454	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP
21630-455	IEC 61587-1, IEC 61587-3	Struktur Pulvermaling	Steel Double Door, Perforated	Varistar CP

YDERLIGERE PRODUKTOPLYSNINGER

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle

Please purchase the grounding kit separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE