


Air Terminal Base, Stamped Adjustable, Imperial Thread

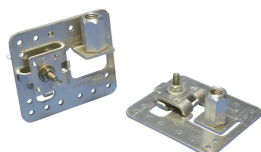

CERTIFICERINGER



FUNKTIONER

For use on flat, vertical or sloping surfaces

Air terminal support tab is field adjustable, eliminating the need for swivel adaptors

Available pre-configured for vertical applications

Install with adhesive or screw down fixings

Positive single bolt tension for multi-directional cable clamping

SPECIFIKATIONER

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/2

Katalognummer	Materiale	Thread Size (TS)	Type	Hole Size (HS)	Dybde (D)	Height (H)
LPC30258	Bronze, Brass	5/8" UNC	Flat	7.14 mm	88.9mm	34.92 mm

Katalognummer	Materiale	Thread Size (TS)	Type	Hole Size (HS)	Dybde (D)	Height (H)
LPC302M16	Bronze, Brass	M16	Flat	7.14 mm	88.9mm	34.92 mm
LPA30258	Aluminium	5/8" UNC	Flat	7.14 mm	88.9mm	34.92 mm
LPC30212	Bronze, Brass	1/2" UNC	Flat	7.14 mm	88.9mm	34.92 mm
LPA30212	Aluminium	1/2" UNC	Flat	7.14 mm	88.9mm	34.92 mm


Table 2/2

Katalognummer	Width (W)
LPC30258	101.6 mm
LPC302M16	101.6 mm
LPA30258	101.6 mm
LPC30212	101.6 mm
LPA30212	101.6 mm

YDERLIGERE PRODUKTOPLYSNINGER

Vertical type bases are factory pre-configured for vertical mount applications.

DIAGRAMS

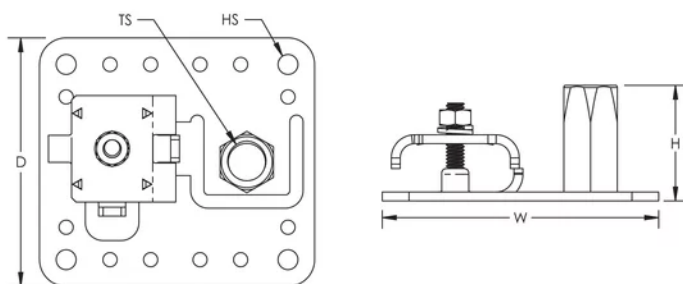

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE