


Cable to Web of Rail Replacement Mold Pair, Signal

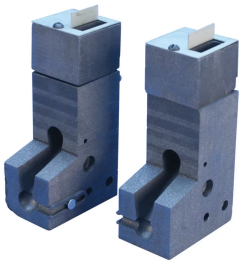

FUNKTIONER

Replacement mold pair designed for the installation of track circuits and jumper bonds to the neutral axis

Sold in pairs

SPECIFIKATIONER

Materiale: Graphite

Table 1/1

Katalognummer	Rail Type	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style	Bond Clips Included
SBB200R	85 lb to 141 lb T-Rail Sections	1" Tab	10 mm ² Stranded	4.12mm	TB5, T21	No
SBB200A	85 lb to 141 lb T-Rail Sections	3/4" XS	3/16" Bondstrand	4.76mm	TB5, T21	Yes
SBB200B	85 lb to 141 lb T-Rail Sections	3/4" Tab	3/16" Bondstrand	4.76mm	TB5, T21	Yes
SBB200C	85 lb to 141 lb T-Rail Sections	1" Tab	3/16" Bondstrand	4.76mm	TB5, T21	Yes
SBB200C12AS	12 lb ASCE	1" Tab	3/16" Bondstrand	4.76mm	T21, TB5	No

Katalognummer	Rail Type	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Welder Style	Bond Clips Included
SBB200D	85 lb to 141 lb T-Rail Sections	1 1/2" Tab	3/16" Bondstrand	4.76mm	T21, TB5	No
SBB200G	85 lb to 141 lb T-Rail Sections	1" Tab	3/16" Bondstrand	4.76mm	T21, TB5	No
SBB200U	RI60	1" Tab	3/16" Bondstrand	4.76mm	TB5, T21	No
SBB200Y	85 lb to 141 lb T-Rail Sections	1" Tab	16 mm ² Concentric	5.18mm	T21, TB5	No
SBB200L	85 lb to 141 lb T-Rail Sections	1" Tab	22 mm ² Ropelay	6.1mm	T21, TB5	No
SBB200X	85 lb to 141 lb T-Rail Sections	1" Tab	25 mm ² Stranded	6.6mm	TB5, T21	No
SBB200P	85 lb to 141 lb T-Rail Sections	1" Tab	35 mm ² Concentric	7.75mm	T21, TB5	Not Required
SBB200E	85 lb to 141 lb T-Rail Sections	1" Tab	5/16" Bondstrand	7.94mm	TB5, T21	Yes

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE