


Cable to Web of Rail T21 Complete Welder, Signal

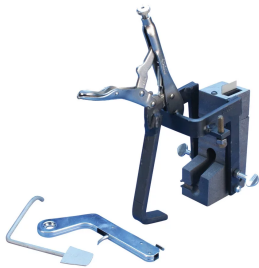

FUNKTIONER

Complete right hand or left hand web welder assembly designed for the installation of track circuits and jumper bonds to the neutral axis of 85 to 141 lb. rail

Includes mold cleaner and flint ignitor

SPECIFIKATIONER

Rail Type: 85 lb to 141 lb T-Rail Sections

Table 1/2

Katalognummer	Artikelnummer	Materiale	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBTBT21YRH		Stål, Graphite	1" Tab	16 mm ² Concentric	5.18mm	T21
SBTBT21YLH		Stål, Graphite	1" Tab	16 mm ² Concentric	5.18mm	T21
SBTBT21XRH		Stål, Graphite	1" Tab	25 mm ² Concentric	6.6mm	T21
SBWT21W6RH	223217	Stål, Graphite	Field-made	50 mm ² Solid	8mm	T21

Katalognummer	Artikelnummer	Materiale	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Welder Style
SBWT21W6LH		Stål, Graphite	Field-made	50 mm ² Solid	8mm	T21

Table 2/2

Katalognummer	Artikelnummer	Orientation
SBTBT21YRH		Right Hand
SBTBT21YLH		Left Hand
SBTBT21XRH		Right Hand
SBWT21W6RH	223217	Right Hand
SBWT21W6LH		Left Hand

DIAGRAMS



ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE