


Cable to Web of Rail TB5 Complete Welder Pair, Signal

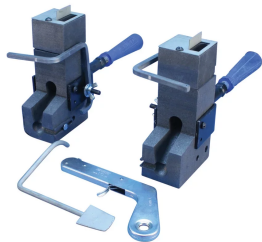

FUNKTIONER

Complete web welder assembly designed for the installation of track circuits and jumper bonds to the neutral axis of 85 to 140 lb. rail

SPECIFIKATIONER

Table 1/1

Katalognummer	Materiale	Rail Type	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBTBTB5B	Steel, Graphite, Thermoplastic	85 lb to 141 lb T-Rail Sections	3/4" Tab	3/16" Bondstrand	4.76mm	TB5
SBTBTB5C	Steel, Graphite, Thermoplastic	85 lb to 141 lb T-Rail Sections	1" Tab	3/16" Bondstrand	4.76mm	TB5
SBTBTB5C12AS	Steel, Graphite, Thermoplastic	12 lb ASCE	1" Tab	3/16" Bondstrand	4.76mm	TB5
SBTBTB5D	Steel, Graphite, Thermoplastic	85 lb to 141 lb T-Rail Sections	1 1/2" Tab	3/16" Bondstrand	4.76mm	TB5
SBTBTB5U	Steel, Graphite, Thermoplastic	RI60 Girder Rail	1" Tab	3/16" Bondstrand	4.76mm	TB5
SBXSTB5A	Graphite, Steel, Thermoplastic	85 lb to 141 lb T-Rail Sections	3/4" XS	3/16" Bondstrand	4.76mm	TB5

Katalognummer	Materiale	Rail Type	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Welder Style
SBTBTB5E	Steel, Graphite, Thermoplastic	85 lb to 141 lb T-Rail Sections	1" Tab	5/16" Bondstrand	7.94mm	TB5

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE