

Compression Coupler for Copper-Bonded Ground Rod, Pointed



CERTIFICERINGER



FUNKTIONER

Threadless compression coupler for use with pointed copper-bonded ground rods

Inside of coupler is tapered so ground rod compresses during installation to form an irreversible conductive connection

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Ground Rod Diameter, Nominal	Length (L)	Unit Weight	Complies With
BR12	156650	Brass	1/2"	70mm	0.13 kg	
CC12F	158000	Silicon Bronze	1/2"	69.8mm	0.13 kg	
CC58	158010	Silicon Bronze	5/8"	69.8mm	0.15 kg	IEC® EN 62561-2

Katalognummer	Artikelnummer	Materiale	Ground Rod Diameter, Nominal	Length (L)	Unit Weight	Complies With
CC34	158020	Silicon Bronze	3/4"	69.8mm	0.2 kg	IEC® EN 62561-2


Table 2/2

Katalognummer	Artikelnummer	Certificeringer
BR12	156650	
CC12F	158000	UL, CSA-US, cUL, CSA
CC58	158010	UL, CSA, cUL, CSA-US, RUS
CC34	158020	CSA, UL, cUL, CSA-US

YDERLIGERE PRODUKTOPLYSNINGER

IEC® EN 62561-2 supercedes EN 50164-2.

DIAGRAMS

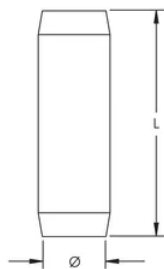

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE