

# ESE Air Terminal for Remote Tester



The nVent ERICO Early Streamer Emission (ESE) Air Terminal for Remote Tester generates controlled magnitude and frequency pulses at the tip of the terminal during high static fields before a lightning discharge. Due to the internal control circuit, the nVent ERICO ESE Air Terminal for Remote Tester enables early launching of an upward leader compared to other passive components. When paired with the nVent ERICO ESE Air Terminal Remote Tester, the need for on-site manual testing is eliminated and creates a more autonomous, continuous monitoring solution.

## FUNKTIONER

Designed and tested to NF C 17-102 and similar standards

Superior corrosion resistance, even in high salinity environments

Quick and easy installation

Compatible with nVent ERICO ESE Air Terminal Remote Tester

Suitable for use with a variety of downconductor systems including tape and stranded conductors in addition to insulated downconductors such as nVent ERICO ISONV and nVent ERICO Ericore conductors

## SPECIFIKATIONER


Table 1/2

| Katalognummer | Complies With                                 | Connects To                           | Triggered Advance, $\Delta T$ | Temperature | Diameter ( $\varnothing$ ) | Height (H) |
|---------------|-----------------------------------------------|---------------------------------------|-------------------------------|-------------|----------------------------|------------|
| SI60I316RT    | NF C17-102:2011, NP 4426:2013, UNE 21186:2011 | ESEAT Remote Tester (SIREMOTETES TER) | 60 $\mu$ s                    | 120 °C Max  | 28 mm                      | 684.6 mm   |

Table 2/2

| Katalognummer | Materiale                        | Thread Size (TS) | Unit Weight |
|---------------|----------------------------------|------------------|-------------|
| SI60I316RT    | Stainless Steel 316L (EN 1.4404) | MF25             | 1.56 kg     |

## DIAGRAMS

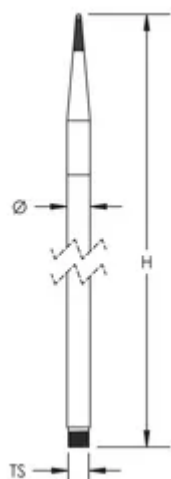

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**