

Ground Rod Clamp, Rod to Conductor, Stainless Steel



CERTIFICERINGER



FUNKTIONER

Unique stamped body design will not crack from excessive torque

Provides a greater surface area contact to allow improved performance of the connector

Compatible with copper, copper bonded, galvanized, stainless steel, rebar and plain steel ground rods and electrodes

SPECIFIKATIONER


Table 1/2

Katalognummer	Artikelnummer	Materiale	Torque (TQ)	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size
SP58	158185	Stainless Steel 304 (EN 1.4301)	16.90 - 33.9 N·m	1/2" - 5/8"	12.7 - 15.9 mm	#10 Stranded - #2 Stranded, 6 mm² Stranded - 25 mm² Stranded

Table 2/2

Katalognummer	Artikelnummer	Wrench Size
SP58	158185	1/2"

DIAGRAMS

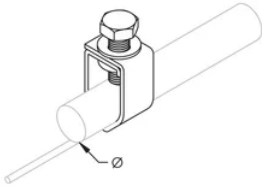

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE