

Ground Rod Driving Point for Ground Rod, Sectional Internal Thread



FUNKTIONER

Threaded ground rod driving point for use only with internally threaded ground rods


SPECIFIKATIONER

Materiale: Stål

Table 1/1

Katalognummer	Artikelnummer	For Use With	Length (L)	Thread Length (TL)	Diameter (Ø)	Thread Size (TS)
SPK15	710120	SSR16 and SCR15 Internally Threaded Ground Rods	42mm	20mm	15 mm	M10
SPK20	710130	SSR20 Internally Threaded Ground Rod	51mm	20mm	20 mm	M10

DIAGRAMS

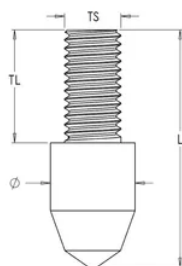

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE