

Inspection Housing, High Density Polyethylene (HDPE)



FUNKTIONER

Pedestrian load rating

Suitable for lighter load rating applications in turf

Chemical, UV and corrosion resistant

3/8" x 2 1/2" (64 mm) stainless steel lock bolt included

Boxes and covers nest in 3 1/4" (83 mm) increments

Two 3 1/2" x 1 1/2" (89 x 38 mm) knockouts per box

T416BH includes four additional holes in the cover to allow water to enter the inspection well, typically for use with chemical ground rods

SPECIFIKATIONER


Table 1/2

Katalognummer	Materiale	Farve	Load Rating	Diameter, Grade Level (DG)	Outer Diameter (OD)	Height (H)
T416B	High Density Polyethylene (HDPE)	Green	0.15	260mm	333 mm	254 mm

Table 2/2

Katalognummer	Unit Weight
T416B	2 kg

DIAGRAMS

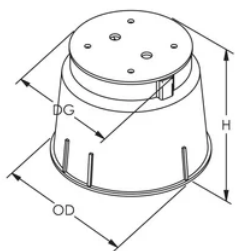

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE