


Joint Bond Mold Pair with Mounting Parts and Clips, Signal

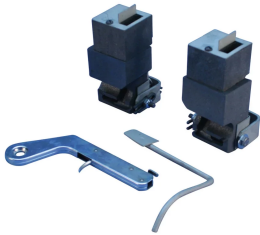

FUNKTIONER

Pair of replacement molds with mounting parts designed for the installation of jumper bonds to the head of the rail

Connection is made within the confines of the splice bar

Includes mold cleaner and flint ignitor

SPECIFIKATIONER

Rail Type: 85 lb to 141 lb T-Rail Sections

Product: Mold, frames, and clips

Table 1/1

Katalognummer	Artikelnummer	Materiale	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBM456F		Stål, Graphite	3/4" XS	3/16" Bondstrand	4.76mm	T6, T7
SBS925F		Stål, Graphite	Head Free	3/16" Bondstrand	4.76mm	T6, T7
SBS5838F	165171	Stål, Graphite	3/4" Tab	3/16" Bondstrand	4.76mm	T6, T7
SBS898F		Stål, Graphite	1" Tab	5/16" Bondstrand	7.94mm	T6, T7

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE