

Load Cell Protector



FUNKTIONER

Six wires and shield protection works with four or six wire systems

Suitable for compression or tension cells

Low series impedance, loadcells do not need recalibration

NEMA®-12 (IP-55) rated, suitable for outdoor use


Helps protect against excitation over-voltage and prevent loadcell damage

SPECIFIKATIONER

Katalognummer	LCP01A
Artikelnummer	701610
Max Discharge Current (Imax), Shield to Ground	10kA 8/20 µs
Max Discharge Current (Imax), Signal to Shield	0.3kA 8/20 µs
Voltage Protection Level (Up), Shield to Ground	90V
Voltage Protection Level (Up), Signal to Shield	30V
Voltage Protection Level (Up), Signal to Signal	15V
Loop Resistance	0.3 Ω
Technology	Silicon Avalanche Diode (SAD)
Materiale	Acrylonitrile Butadiene Styrene
Enclosure Rating	NEMA® 12 (IP55)
Dybde (D)	110mm
Height (H)	56 mm

Katalognummer	LCP01A
Width (W)	75 mm
Unit Weight	0.25 kg
Temperature	-40 to 80 °C

DIAGRAMS

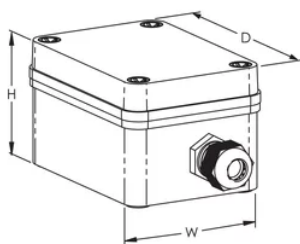

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE