


Mesh Bonding Network Connector, MBNC240

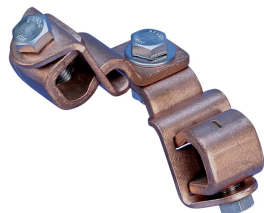

CERTIFICERINGER



FUNKTIONER

Allows for fast, simple and economical field connection of grounding and bonding wires

Heavy duty clamps with stainless steel hardware are suitable for direct burial

Can accommodate additional pigtails that can be used to connect to building steel and equipment

Can be combined with Universal Pedestal Clamp for bonding to various pedestal sizes for mesh bonding networks


SPECIFIKATIONER

Table 1/1

Katalognummer	Materiale	Conductor Size	nVent ERICO Cu-Bond Conductor	Complies With
MBNC240	Copper, Stainless Steel 304 (EN 1.4301)	#2 Solid - 4/0 Stranded, 35 mm ² - 100 mm ²	CBSC8, CBSC10, CBSC13	IEC® 62561-1

YDERLIGERE PRODUKTOPLYSNINGER

IEC compliance is valid only for nVent ERICO Cu-Bond Conductors listed.

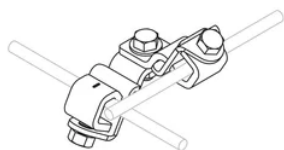

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte