

Multi-Purpose Grounding Clamp, Stainless Steel



FUNKTIONER

Convenient multi-purpose clamp designed to accommodate round conductors, flat conductors, ground rods and rebar

Stainless steel material with inner plate allows compatibility between most dissimilar metals

SPEKIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Conductor Size	Tape Size	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)
MPSC404SS	120319	Stainless Steel 304 (EN 1.4301)	35 mm ² Stranded - 50 mm ² Stranded, #2 Stranded - 1/0 Solid	40 x 4 mm Max	5/8" - 3/4"	14.2 - 19 mm

Table 2/3


Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Length (L)	Width (W)
MPSC404SS	120319	16 - 20 mm	#5 - #6	15M - 20M	65mm	65 mm

Table 3/3

Katalognummer	Artikelnummer	Torque (TQ)	Complies With
---------------	---------------	-------------	---------------

MPSC404SS	120319	23 N·m	IEC® EN 62561-1
-----------	--------	--------	-----------------

DIAGRAMS

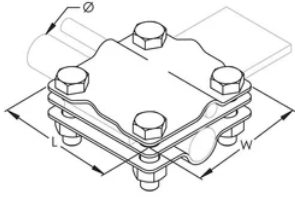

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE