

# nVent ERICO Railclips, Hammer-On, Conductor Parallel Outside



## FUNKTIONER

"Hammer-on" design

Securely holds conductors, reducing maintenance and improving wayside safety

Quick and easy hammer-on installation

Fits various rail profiles

Does not require removal of the ballast material

Multi-layer proprietary coating provides optimal corrosion protection

## SPECIFIKATIONER

**Rail Type:** 40 kg to 65 kg T-Rail Sections


**Finish:** Multi-Layer Proprietary Coating; Cataphoresis and Polyester Black Treatment

**Materiale:** Spring Steel

Table 1/1

| Katalognummer | Artikelnummer | Length (L) | Width (W) | Rail Foot Thickness (RFT) | Diameter (Ø)  |
|---------------|---------------|------------|-----------|---------------------------|---------------|
| EM58SN4SH     | 595380        | 65mm       | 44 mm     | 8 - 14 mm                 | 13.5 - 155 mm |
| EM58SN3SH     | 595330        | 70mm       | 44 mm     | 8 - 14 mm                 | 25 - 28 mm    |

## DIAGRAMS

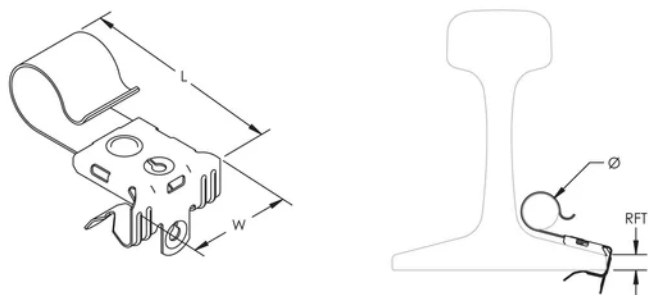

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**