

Rail Base Temporary Bond Connector, T-Handle



FUNKTIONER

Can be used on most common rail types

Makes temporary signal bonds and track circuit connections using customer-supplied cable

Hardened contact points on clamps bite through rust and scale

Single conductor connection; solid or stranded

Unique design assures positive contact and firm grip

T-shaped handle allows quick and easy tightening by hand

SPECIFIKATIONER


Table 1/2

Katalognummer	Materiale	Length (L)	Width (W)	Height (H)	Rail Foot Thickness (RFT)	Diameter (Ø)
A140WT	Stål, Copper	63.5mm	25.4 mm	47.63 mm	15.24 mm Max	4.0 - 9.5 mm

Table 2/2

Katalognummer	Conductor Size
A140WT	#6 Solid - 1/0 Stranded, 10 mm ² Solid - 50 mm ² Stranded

DIAGRAMS

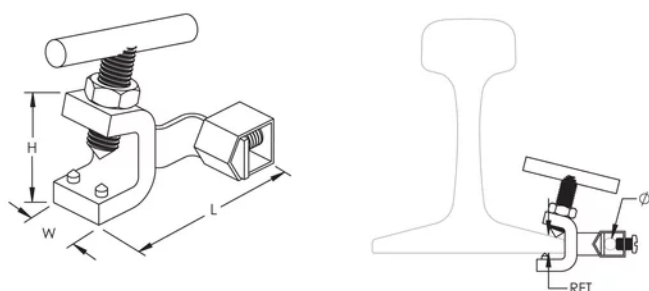

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE