

Rail Four Post Terminal Block



FUNKTIONER

Separates "clean" wiring from "dirty" wiring

Includes integrated test terminal

Includes slot for low-impedance busbar

Modular design for field assembly and future expansion

Meets AAR recommendations

SPECIFIKATIONER

Table 1/2

Katalognummer	Length (L)	Dybde (D)	Height (H)	A	B	Thread Size (TS)
B2700A2C1WH	133.35mm	25.4mm	31.75 mm	25.4 mm	60.3 mm	14" UNS
SBB2700A2B10	133.35mm	25.4mm	31.75 mm	25.4 mm	60.3 mm	14" UNS

Table 2/2

Katalognummer	Hardware Included
B2700A2C1WH	Yes
SBB2700A2B10	No


YDERLIGERE PRODUKTOPLYSNINGER

B2700A2C1WH kit includes: (1) terminal block, (1) offset test link, (15) 9/16" outer diameter copper flat washers, (9) zinc plated binding 14-24 UNS-2B hex nuts AAR, (5) nickel plated jam 14-24 UNS-2B hex nuts AAR, (2) #10X1 – 1/2" zinc plated screws, and (1) instruction print.

Four Post Terminal Blocks are components included in nVent ERICO pre-engineered and manufactured panels.

Design assistance is available for special applications. Contact your nVent ERICO representative for more details.

DIAGRAMS

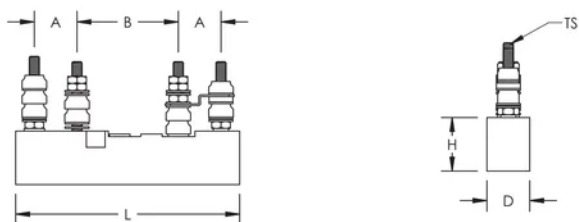

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE