



# Rebar Grounding Clamp, Heavy Duty

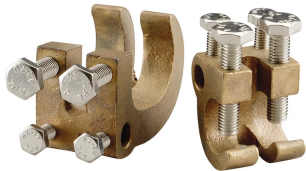

## CERTIFICERINGER

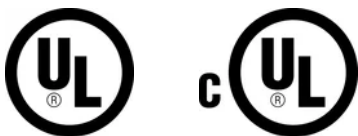

## FUNKTIONER

Provides two connection points to concrete encased electrodes (rebar) for states where the Authority Having Jurisdiction (AHJ) requires it

Meets 2005 NEC® standard requirement for bonding to rebar into the grounding system

Suitable for direct burial applications

Has high-strength bronze alloy construction

Easy to install

## SPECIFIKATIONER


**Materiale:** Bronze

Table 1/1

| Katalognummer | Artikelnummer | Conductor Size                                                                                 | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Certificeringer |
|---------------|---------------|------------------------------------------------------------------------------------------------|--------------------|----------------|--------------------|-----------------|
| RC70          | 710325        | #8 Solid - 2/0<br>Stranded, 10<br>mm <sup>2</sup> Stranded -<br>70 mm <sup>2</sup><br>Stranded | 8 - 18 mm          | #3 - #6        | 10M - 20M          | UL              |

| Katalognummer | Artikelnummer | Conductor Size                                                                                  | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Certificeringer |
|---------------|---------------|-------------------------------------------------------------------------------------------------|--------------------|----------------|--------------------|-----------------|
| RC100         | 710335        | #8 Solid - 4/0<br>Stranded, 10<br>mm <sup>2</sup> Stranded -<br>100 mm <sup>2</sup><br>Stranded | 18 - 36 mm         | #6 – #11       | 20M – 35M          | UL, cUL         |

## DIAGRAMS

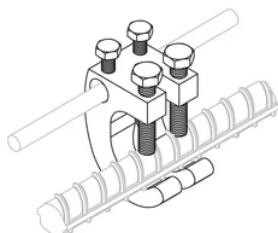

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE