

SB/SBL Hollow Core Rail Drill Bit



FUNKTIONER

Designed for high-speed drilling applications

Withstands approximately 40 uses

Can be reground for further use

Specifically developed for rail steel

3/4" (19 mm) Weldon shank

Allows for short drill times

High durability provides extended lifetime

SPECIFIKATIONER

Materiale: High-Speed Steel


Finish: TIALN Coating

Table 1/1

Katalognummer	Artikelnummer	Drill Bit Diameter (Ø)	Length (L)
DHC36	716498	36 mm	63mm
DHC25	716495	25 mm	63mm
DHC23	716494	23 mm	63mm
DHC27	716496	27 mm	63mm

Katalognummer	Artikelnummer	Drill Bit Diameter (Ø)	Length (L)
DHC19	716493	19 mm	63mm
DHC35	716497	35 mm	63mm
DHC18	716492	18 mm	63mm
DSB1670	715251	16 mm	70mm
DSB1770	715252	17 mm	70mm
DSBL1690	716301	16 mm	90mm

DIAGRAMS

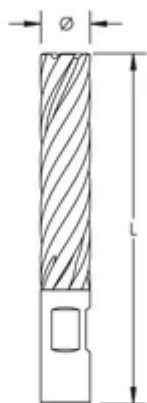

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE