


Swan-Neck Link

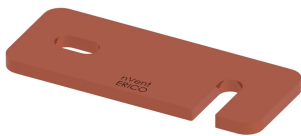

FUNKTIONER

Standalone link that joins two or more nVent ERICO electrical earth bars

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

SPECIFIKATIONER

Materiale: Copper


Table 1/1

Katalognummer	Finish	Width (W)	Thickness (T)	Unit Weight
EEBDLC	Bare	50 mm	6 mm	0.3 kg
EEBDLT	Tinned	50 mm	6 mm	0.3 kg

YDERLIGERE PRODUKTOPLYSNINGER

Tinned finish is 8 microns according to ASTM B545 Service Class "C" for corrosive environments.

DIAGRAMS

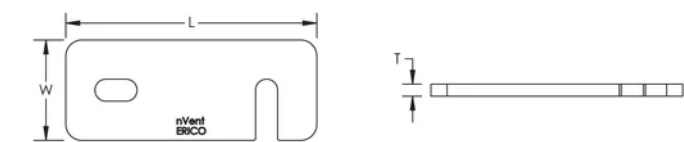

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE