

Threaded Coupler for Copper-Bonded Ground Rod, Threaded



CERTIFICERINGER



FUNKTIONER

High-strength couplings are threaded and chamfered at both ends for easy driving

Corrosion-resistant couplings ensure permanent, low resistance copper-to-copper connections

SPECIFIKATIONER


Table 1/2

Katalognummer	Artikelnummer	Materiale	Ground Rod Diameter, Nominal	Length (L)	Thread Size (TS)	Unit Weight
CR58	158040	Bronze	5/8"	61mm	5/8" UNC	0.1 kg
SC34	158050	Bronze	3/4"	71mm	3/4" UNC	0.17 kg
CR100		Silicon Bronze	1"	99.1mm	1" UNC	0.35 kg

Table 2/2

Katalognummer	Artikelnummer	Complies With	Certificeringer
CR58	158040	EN IEC 62561-2	UL, CSA, cUL, CSA-US, RUS
SC34	158050	IEC® EN 62561-2	
CR100		EN IEC 62561-2	cUL, UL

DIAGRAMS

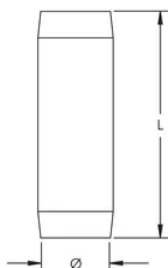

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE