

Universal Conductor Clip, Plastic



FUNKTIONER

Secures either round or tape conductors

Can be mechanically fastened to a surface or attached to plastic adhesive bases

UV resistant, designed and tested for outdoor use

Material UV performance meets the UL® 746C standard

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Temperature	Conductor Size	Tape Size	Dybde (D)
PDCUC	711352	Polycarbonate	-20 to 120 °C	8 mm ² Stranded, 8 mm ² Solid	25 x 3 mm, 26 x 2 mm	20mm


Table 2/2

Katalognummer	Artikelnummer	Width (W)	Hole Size (HS)	Static Load	Unit Weight
PDCUC	711352	35.9 mm	6.8 mm	1000N	0.01 kg

YDERLIGERE PRODUKTOPLYSNINGER

When using the adhesive base, recommended installation temperatures are limited to 15 °C to 38 °C (59 °F to 100 °F).

DIAGRAMS

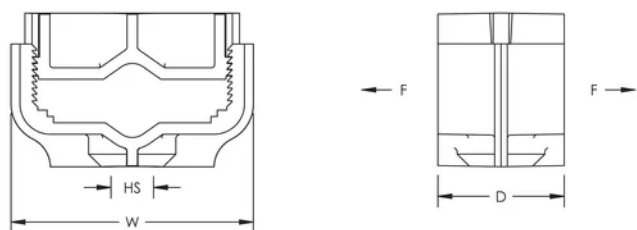

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE