


Universal Pedestal Clamp with Cable Management, MBNUPCJ240



CERTIFICERINGER

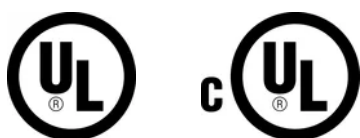

FUNKTIONER

Only one attachment required for both mesh bonding and cable management

Eliminates the need for separate mounting brackets for different pedestal types or sizes

Stainless steel construction of bracket and hardware reduces potential for galvanic corrosion

Mesh bonding conductors do not have to bend around each pedestal to conform to grid pattern


Suitable for round or square pedestals

SPECIFIKATIONER

Table 1/1

Katalognummer	Materiale	Finish	Conductor Size	Pedestal Size
MBNUPCJ240	Copper, Stål, Stainless Stål 304 (EN 1.4301)	nVent CADDY Armour, Electrogalvanized	#2 Solid - 4/0 Stranded, 35 mm ² - 100 mm ²	22 - 51 mm Round or Square

DIAGRAMS

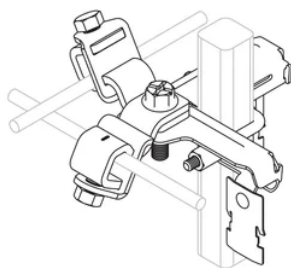

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE