

Universal Transient Barrier, Modem/Telephone



CERTIFICERINGER



FUNKTIONER

General purpose barrier provides protection of low-voltage circuits and transducers

Separate plug and base design allows hot swappable module replacement


Multi-stage protection and fine over-voltage protection helps ensure lowest residual surge voltages reach sensitive equipment

SPECIFIKATIONER

Katalognummer	UTBTA
Artikelnummer	702850
Max Continuous Operating Voltage (Uc)	280 V
Rated Load Current (IL)	160mA
Frequency	15 MHz
Loop Resistance	1 Ω
Max Discharge Current (Imax), Per Mode	0.5kA 8/20 μs
Technology	Gas Discharge Tube (GDT) PTC

Katalognummer	UTBTA
Voltage Protection Level (Up), L-L	480 V @ 3 kA
Connection, Stranded	1 - 4 mm ²
Mounting	35 mm top hat DIN rail
Temperature	-20 to 65 °C
Enclosure Material	UL® 94V-0 Thermoplastic
Enclosure Rating	IP 20 NEMA®-1
Dybde (D)	68mm
Height (H)	90 mm
Width (W)	18 mm
Unit Weight	0.1 kg
Certification Details	UL® 497A
Complies With	ANSI®/IEEE® C62.41.2-2002 Cat A, Cat B, Cat C
Replacement Module	UTBTM

DIAGRAMS

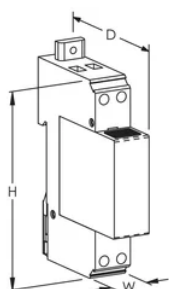

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE