

ABS Adjustable Busbar Support Insulator Module



CERTIFICERINGER



FUNKTIONER

Modules provide flexibility to select distance between phases and supports

Extremely robust construction

Halogen free insulators

RoHS compliant

SPECIFIKATIONER

Max Working Voltage, IEC (Ui):	1000;1500
Finish:	Electrogalvanized
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C

Table 1/2

Katalognummer	Artikelnummer	Materiale	Typical Application Current Rating	Busbars per Phase	Busbar Thickness	Busbar Width
---------------	---------------	-----------	------------------------------------	-------------------	------------------	--------------

ABS1-5MOD	560860	Stål, Glass Fibre Reinforced Polyamide, Stainless Stål 304 (EN 1.4301)	1700 A Max	1	5 mm	50 - 125 mm
ABS4-5MOD	560870	Stål, Glass Fibre Reinforced Polyamide, Stainless Stål 304 (EN 1.4301)	3500 A Max	1 - 4	5 mm	50 - 125 mm
ABS1-10MOD	560880	Stål, Glass Fibre Reinforced Polyamide, Stainless Stål 304 (EN 1.4301)	2250 A Max	1	10 mm	50 - 125 mm
ABS2-10MOD	560890	Stål, Glass Fibre Reinforced Polyamide, Stainless Stål 304 (EN 1.4301)	3600 A Max	1 - 2	10 mm	50 - 125 mm
ABS3-10MOD	560900	Stål, Glass Fibre Reinforced Polyamide, Stainless Stål 304 (EN 1.4301)	4500 A Max	1 - 3	10 mm	50 - 125 mm


Table 2/2

Katalognummer	Artikelnummer	Width (W)	Dybde (D)	Unit Weight
ABS1-5MOD	560860	74 mm	67mm	0.64 kg
ABS4-5MOD	560870	99 mm	67mm	0.73 kg
ABS1-10MOD	560880	74 mm	67mm	0.64 kg
ABS2-10MOD	560890	99 mm	67mm	0.73 kg
ABS3-10MOD	560900	124 mm	67mm	0.81 kg

YDERLIGERE PRODUKTOPLYSNINGER

ABS Adjustable Busbar Support High Ampacity Kit available to support up to 200 mm (7.87") busbar width for applications up to 7400 A.

DIAGRAMS

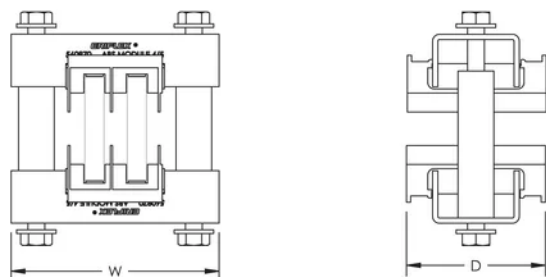

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE