

BC Ribbed Steel Busbar Clamp



CERTIFICERINGER



FUNKTIONER

Connects two copper busbars together or nVent ERIFLEX Flexibar to copper busbar

Two ribbed plates complete with screws

Allows for excellent electrical contact

Installs quickly and easily

Ideal for on site modifications

RoHS compliant

SPECIFIKATIONER

Clamping Capacity: 20mm

Finish: Electrogalvanized

Materiale: Stål


Table 1/2

Katalognummer	Artikelnummer	Busbar Width	Width (W)	A	Screw Diameter (Sc)	Torque (TQ)
BC80	553250	80 mm	118 mm	96 mm	10	29.5 N·m

Katalognummer	Artikelnummer	Busbar Width	Width (W)	A	ScrewDiameter (Sc)	Torque (TQ)
BC30	553200	30 mm	56 mm	42 mm	6	7 N·m
BC40	553210	40 mm	66 mm	52 mm	6	7 N·m
BC50	553220	50 mm	83 mm	64 mm	8	20 N·m
BC63	553230	63 mm	93 mm	74 mm	8	20 N·m
BC100	553260	100 mm	144 mm	118 mm	10	29.5 N·m

Table 2/2		
Katalognummer	Artikelnummer	Unit Weight
BC80	553250	0.12 kg
BC30	553200	0.31 kg
BC40	553210	0.37 kg
BC50	553220	0.59 kg
BC63	553230	0.74 kg
BC100	553260	1.72 kg

DIAGRAMS

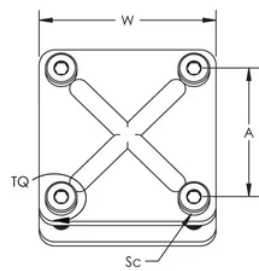

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE