


BS-250A Four Pole Insulating Support

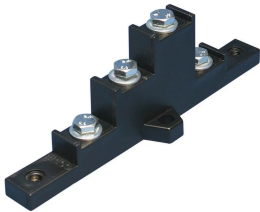

CERTIFICERINGER



FUNKTIONER

Create custom four pole distribution blocks for an electrical distribution system

Mounts with screws

Protection screen can be fixed using spacers

Halogen free

RoHS compliant

SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Finish	Max Working Voltage, IEC (Ui)	Working Temperature	Typical Application Current Rating
BS-250A	551300	Stål, Glass Fibre Reinforced Polyamide	Electrogalvanized	630, 630	-40 to 130 °C	160 - 250 A

Table 2/3

Katalognummer	Artikelnummer	Complies With	Flammability Rating	Busbar Width	Busbar Thickness	Dybde (D)
---------------	---------------	---------------	---------------------	--------------	------------------	-----------

BS-250A	551300	IEC® 60439.1, IEC® 61439.1, IEC® 60695-2-11 (Glow Wire Test 960 °C)	UL® 94V-0	15 - 20 mm	5 mm	45mm
---------	--------	--	-----------	------------	------	------


Table 3/3

Katalognummer	Artikelnummer	Height (H)	A	Screw Diameter (Sc)	Unit Weight
BS-250A	551300	150 mm	130 mm	6	0.05 kg

YDERLIGERE PRODUKTOPLYSNINGER

Must be used with copper busbars.

DIAGRAMS

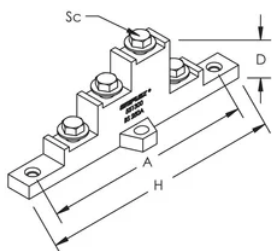

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE