

CABS Busbar Support Kit



CERTIFICERINGER



FUNKTIONER

For all busbar types

Improve bending resistance by interlocking or stacking two profiles

Quick and easy to install

Halogen free insulators

RoHS compliant

SPECIFIKATIONER

Typical Application Current Rating:	400 - 4500 A
Max Working Voltage, IEC (Ui):	1000;1500
Finish:	Electrogalvanized
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C

Table 1/2


Katalognummer	Artikelnummer	Materiale	Busbars per Phase	Busbar Width	Busbar Thickness	Dybde (D)
---------------	---------------	-----------	-------------------	--------------	------------------	-----------

CABS4-5TN-400	549310	Aluminum, Glass Fibre Reinforced Polyamide, Stål	1 - 4	30 - 125 mm	5 mm	39mm
CABS4-5TN-600	549260	Aluminum, Glass Fibre Reinforced Polyamide, Stål	1 - 4	30 - 125 mm	5 mm	39mm
CABS2-10TN-400	549320	Aluminum, Glass Fibre Reinforced Polyamide, Stål	1 - 2	30 - 120 mm	10 mm	39mm
CABS2-10TN-600	549270	Aluminum, Glass Fibre Reinforced Polyamide, Stål	1 - 2	30 - 120 mm	10 mm	39mm

Table 2/2

Katalognummer	Artikelnummer	Width (W)	A	B	C	Unit Weight
CABS4-5TN-400	549310	350 mm	300 mm	75 mm	325 mm	0.8 kg
CABS4-5TN-600	549260	550 mm	500 mm	75 - 125 mm	525 mm	0.84 kg
CABS2-10TN-400	549320	350 mm	300 mm	75 mm	325 mm	0.77 kg
CABS2-10TN-600	549270	550 mm	500 mm	75 - 125 mm	525 mm	0.81 kg

DIAGRAMS

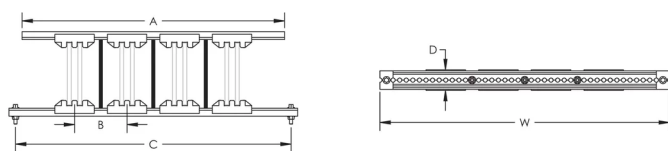

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE