

Compact Busbar Support with Neutral Circuit



CERTIFICERINGER



FUNKTIONER

Compact design fits in 400 mm (15 3/4") deep panels

Includes mounting holes for direct fixing of protection screen

Installs quickly and easily

Halogen free

RoHS compliant

SPECIFIKATIONER

Busbar Width:	25 - 80 mm
Typical Application Current Rating:	250 - 1600 A
Max Working Voltage, IEC (Ui):	1000;1500
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C

Table 1/2


Katalognummer	Artikelnummer	Materiale	Busbars per Phase	Busbar Thickness	Width (W)	A
---------------	---------------	-----------	-------------------	------------------	-----------	---

CBS-B2-5TN	551151	Aluminum, Glass Fibre Reinforced Polyamide	1 - 2	5 mm	338 - 390 mm	290 mm
CBS-B1-10TN	551181	Aluminum, Glass Fibre Reinforced Polyamide	1	10 mm	338 - 390 mm	290 mm

Table 2/2

Katalognummer	Artikelnummer	B	C	D	X
CBS-B2-5TN	551151	65 mm	325 - 377 mm	65 mm	6.5 x 23 mm
CBS-B1-10TN	551181	60 mm	325 - 377 mm	65 mm	6.5 x 23 mm

DIAGRAMS

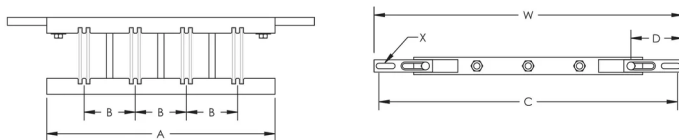

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE