

DPCB Punched Plain Copper Busbar, Double



CERTIFICERINGER



FUNKTIONER

Heavy-duty power connection

Circuit breaker, generator and prefabricated power network conductor

Alternative to large and multiple cables

Earth/ground connection

Power distribution

Rounded edges

SPECIFIKATIONER

Materiale: Copper

Table 1/2

Katalognummer	Artikelnummer	Width (W)	Thickness (T)	Length (L)	Hole Size (HS)	A
DPCB100X5	550440	100 mm	5 mm	1750mm	10.5 mm	75 mm


Katalognummer	Artikelnummer	Width (W)	Thickness (T)	Length (L)	Hole Size (HS)	A
DPCB125X5	550450	125 mm	5 mm	1750mm	10.5 mm	100 mm
DPCB50X5	550410	50 mm	5 mm	1750mm	10.5 mm	25 mm
DPCB63X5	550420	63 mm	5 mm	1750mm	10.5 mm	38 mm
DPCB80X5	550430	80 mm	5 mm	1750mm	10.5 mm	55 mm
DPCB100X10	550380	100 mm	10 mm	1750mm	10.5 mm	75 mm
DPCB120X10	550390	120 mm	10 mm	1750mm	10.5 mm	95 mm
DPCB50X10	550350	50 mm	10 mm	1750mm	10.5 mm	25 mm
DPCB60X10	550360	60 mm	10 mm	1750mm	10.5 mm	35 mm
DPCB80X10	550370	80 mm	10 mm	1750mm	10.5 mm	55 mm

Table 2/2

Katalognummer	Artikelnummer	B	C	Unit Weight
DPCB100X5	550440	25 mm	12.5 mm	7.25 kg
DPCB125X5	550450	25 mm	12.5 mm	9.2 kg
DPCB50X5	550410	25 mm	12.5 mm	3.4 kg
DPCB63X5	550420	25 mm	12.5 mm	4.4 kg
DPCB80X5	550430	25 mm	12.5 mm	5.7 kg
DPCB100X10	550380	25 mm	12.5 mm	14.5 kg
DPCB120X10	550390	25 mm	12.5 mm	18.4 kg
DPCB50X10	550350	25 mm	12.5 mm	6.8 kg

Katalognummer	Artikelnummer	B	C	Unit Weight
DPCB60X10	550360	25 mm	12.5 mm	8.8 kg
DPCB80X10	550370	25 mm	12.5 mm	11.4 kg

DIAGRAMS

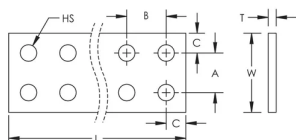

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE