

EC16 Earthing/Grounding Connector



CERTIFICERINGER



FUNKTIONER

Very compact clamp for connecting cable conductors to earthing busbar without drilling

Conductor is clamped with a pressure plate

Clamps can be mounted and slid into position on busbar prior to connecting conductors

Connections can be added after busbar has been mounted

Single screw locks clamp and makes connection

EAC compliant

RoHS compliant

SPECIFIKATIONER

Finish: Electrogalvanized

Materiale: Stål

Table 1/2


Katalognummer	Artikelnummer	Conductor Size	Busbar Thickness	Busbar Width	Dybde (D)	Width (W)
---------------	---------------	----------------	------------------	--------------	-----------	-----------

EC16-5	553480	2.5 mm ² Solid - 16 mm ² Stranded	5 mm	12 mm	15mm	14 mm
EC16-4	553460	2.5 mm ² Solid - 16 mm ² Stranded	4 mm	12 mm	15mm	15 mm

Table 2/2

Katalognummer	Artikelnummer	A	Unit Weight
EC16-5	553480	21.85 mm	0.01 kg
EC16-4	553460	21.85 mm	0.01 kg

DIAGRAMS

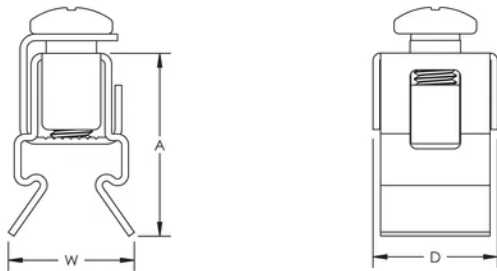

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE