

FS Spacer Clamp, Snap Close



CERTIFICERINGER



FUNKTIONER

Provides support for nVent ERIFLEX Flexibar and insulated braided conductors without damaging the insulation

Ensures correct spacing for optimum cooling

Supports up to four conductors in parallel

Easy to install

Halogen free

RoHS compliant

SPECIFIKATIONER

Materiale:	Polyamide
Flammability Rating:	UL® 94HB
Working Temperature:	-40 to 130 °C

Table 1/1


Katalognummer	Artikelnummer	Conductor Width	Height (H)	Length (L)	Hole Size (HS)	Unit Weight
FS24	553550	24 mm Max	67 mm	30mm	7 mm	0.01 kg

Katalognummer	Artikelnummer	Conductor Width	Height (H)	Length (L)	Hole Size (HS)	Unit Weight
FS32	553560	32 mm Max	67 mm	38mm	7 mm	0.02 kg

YDERLIGERE PRODUKTOPLYSNINGER

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

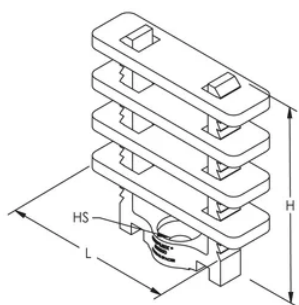

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE