


FSSB Flat Braid in Coil, Stainless Steel

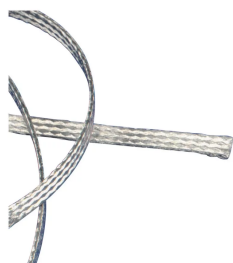

CERTIFICERINGER



FUNKTIONER

High-quality durable stainless steel 316L provides superior abrasion, corrosion, chemical, and UV resistance for outdoor and corrosive applications

Non-magnetic material

Durability of product lengthens cycle time between maintenance

SPECIFIKATIONER

Materiale: Stainless Steel 316L (EN 1.4404)

Table 1/2

Katalognummer	Artikelnummer	Cross Section	Wire Diameter	Length	Thickness	Width
FSSB25-50	557390	50mm ²	0.25mm	25m	3 mm	30 mm
FSSB25-16	557160	16mm ²	0.25mm	25m	1.5 mm	15 mm
FSSB25-25	557170	25mm ²	0.25mm	25m	1.5 mm	23 mm

Table 2/2

Katalognummer	Artikelnummer	Unit Weight
FSSB25-50	557390	0.44 kg
FSSB25-16	557160	0.14 kg
FSSB25-25	557170	0.22 kg

YDERLIGERE PRODUKTOPLYSNINGER

Unit weight is per meter (3.28').

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE