


FTCBI Insulated Flat Braid in Coil, Tinned Copper

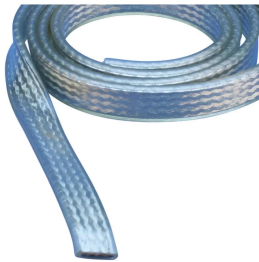

CERTIFICERINGER



FUNKTIONER

Braids in coil are mainly used for power distribution or earthing applications

Non-magnetic material

Tinned finish provides a theft-deterrent appearance

SPECIFIKATIONER

Materiale: Copper;Polyvinylchloride

Finish: Tinned

Table 1/2

Katalognummer	Artikelnummer	Nominal Current	Cross Section	Number of Wires	Wire Diameter	Length
FTCBI25	510310	150A	25mm ²	1404	0.15mm	25m
FTCBI50	510340	250A	50mm ²	2848	0.15mm	25m

Katalognummer	Artikelnummer	Nominal Current	Cross Section	Number of Wires	Wire Diameter	Length
FTCBI16	510300	120A	16mm ²	896	0.15mm	25m

Table 2/2

Katalognummer	Artikelnummer	Thickness	Width	Unit Weight
FTCBI25	510310	3.5 mm	25 mm	0.29 kg
FTCBI50	510340	5 mm	30 mm	0.6 kg
FTCBI16	510300	3.5 mm	17 mm	0.18 kg

Insulation Thickness: 1 mm
Insulation Voltage: 450V
Flammability Rating: UL® 94V-0
Temperature: 70 °C Max

YDERLIGERE PRODUKTOPLYSNINGER

Unit weight is per meter (3.28').

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE