

HCBC High Current Busbar Clamp



CERTIFICERINGER



FUNKTIONER

Connects copper busbar to copper busbar, nVent ERIFLEX Flexibar or power shunt

Made with non-magnetic materials for high current connections between nVent ERIFLEX Flexibar and rigid busbars such as transformer terminals

Rigid design assures even contact pressure

Installs quickly and easily

Ideal for on site modifications

RoHS compliant

SPECIFIKATIONER

Clamping Capacity: 40mm

Materiale: Stainless Steel 304 (EN 1.4301)

Table 1/2

Katalognummer	Artikelnummer	Conductor Width	Dybde (D)	Height (H)	Width (W)	Thickness (T)
HCBC80	553100	80 mm	20mm	43 mm	140 mm	4 mm

Katalognummer	Artikelnummer	Conductor Width	Dybde (D)	Height (H)	Width (W)	Thickness (T)
HCBC120	553120	120 mm	20mm	43 mm	180 mm	4 mm
HCBC100	553110	100 mm	20mm	43 mm	160 mm	4 mm


Table 2/2

Katalognummer	Artikelnummer	Torque (TQ)	Unit Weight
HCBC80	553100	100 N·m	0.84 kg
HCBC120	553120	100 N·m	1 kg
HCBC100	553110	100 N·m	0.92 kg

YDERLIGERE PRODUKTOPLYSNINGER

Use two clamps for optimal contact pressure.

DIAGRAMS

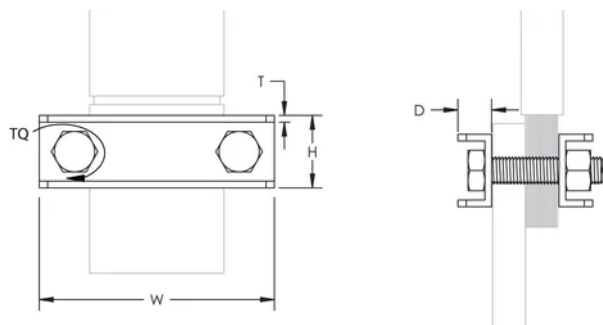

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE