

Hydraulic Flexible/Non-Flexible Busbar Bender



CERTIFICERINGER



FUNKTIONER

Works with copper or aluminium busbar and nVent ERIFLEX Flexibar

Multi-function tool creates "V" or "Z" bends and straightens busbar for corrections

Removable top plate allows for multiple bends on a busbar

Bottom plate is etched to indicate a 90° bend

Includes steel bar supports for bending busbar when tool is not fixed to the Hydraulic nVent ERIFLEX Flexibar and Busbar Work Center

RoHS compliant

SPECIFIKATIONER

Table 1/2


Katalognummer	Artikelnummer	Busbar Width	Busbar Thickness	Bending Angle	Bending Radius	Dybde (D)
HYDR-BB-BEN	545670	200 mm Max	12.7 mm Max	100 ° Max	12.5mm	500mm

Table 2/2

Katalognummer	Artikelnummer	Height (H)	Width (W)	Unit Weight
---------------	---------------	------------	-----------	-------------

HYDR-BB-BEN	545670	261 mm	230 mm	51 kg
-------------	--------	--------	--------	-------

DIAGRAMS

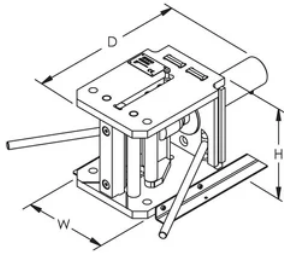

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE