

MFWC Manual nVent ERIFLEX Flexibar Work Center



CERTIFICERINGER



FUNKTIONER

Modular table with large work surface and storage for manual nVent ERIFLEX Flexibar tools

Tools can be fixed directly to interchangeable tiles allowing tools to be quickly moved from one level to another

Non-slip bakelite coated plywood tiles fix into place with included wing knobs

Includes nVent ERIFLEX Flexibar Small Bending and Folding Tool

Forklift rail, locking directional wheels and built-in handles provide easy mobility

Built-in handle is extendable to accommodate long pieces of nVent ERIFLEX Flexibar

SPECIFIKATIONER


Table 1/2

Katalognummer	Artikelnummer	Materiale	Height (H)	Length	Width (W)	A
MFWC	558940	Stål, Plywood	928 mm	1200 - 1913 mm	700 mm	348 mm

Table 2/2

Katalognummer	Artikelnummer	Static Load	Unit Weight
MFWC	558940	400N	95 kg

DIAGRAMS

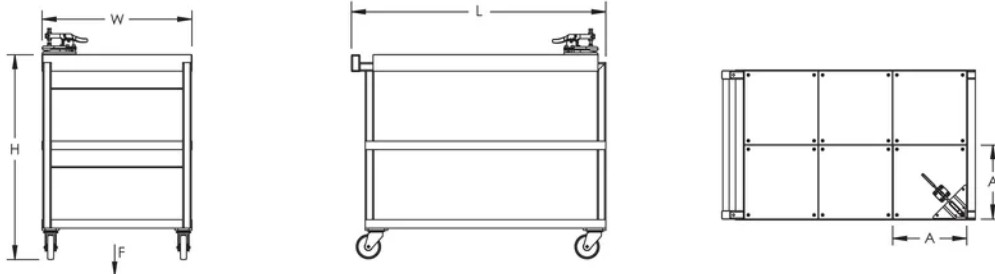

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE