

nVent ERIFLEX Flexbus HCBC Plate



CERTIFICERINGER



FUNKTIONER

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows Flexbus Conductor insulation to overlap the connection palm

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

SPECIFIKATIONER

Materiale: Copper

Finish: Tinned

Table 1/2

Katalognummer	Artikelnummer	A	B	C	D	Thickness (T)
FLEXPLATE50	508180	65 mm	63 mm	45 mm	41 mm	5 mm
FLEXPLATE100	508181	115 mm	63 mm	45 mm	51 mm	5 mm


Table 2/2

Katalognummer	Artikelnummer	Conductor Size	Unit Weight
FLEXPLATE50	508180	220 mm ² , 360 mm ² , 545 mm ² , 640 mm ²	0.16 kg
FLEXPLATE100	508181	960 mm ² , 1280 mm ² , 1810 mm ²	0.32 kg

YDERLIGERE PRODUKTOPLYSNINGER

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

DIAGRAMS

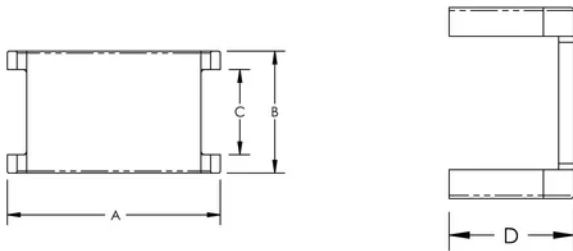

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE