

nVent ERIFLEX Flexbus Transformer Cover IP2X for 1 Conductor per Phase



CERTIFICERINGER



FUNKTIONER

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

SPECIFIKATIONER

Table 1/2


Katalognummer	Artikelnummer	Materiale	Working Temperature	Length (L)	Width (W)	Dybde (D)
FLEXCOVIP2XONE	508160	Polyvinylchloride	-40 to 140 °C	465mm	182 mm	126mm

Table 2/2

Katalognummer	Artikelnummer	Unit Weight
---------------	---------------	-------------

FLEXCOVIP2XONE	508160	0.53 kg
----------------	--------	---------

DIAGRAMS

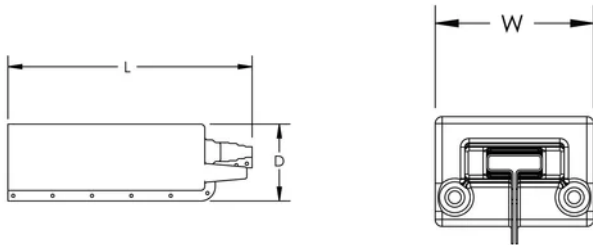

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE