

TR Four Pole Distribution Block, 125 A



CERTIFICERINGER



FUNKTIONER

Easily clips onto DIN rail or mounts to panel with screws

Equipped with a current input plug

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER

Katalognummer	TR-125A
Artikelnummer	563150
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass
Max Working Voltage, IEC (Ui)	1000


Katalognummer	TR-125A
Peak Short Circuit Current (I _{pk})	40kA
Short Term Withstand Current (I _{cw}) 1s	8.4kA
Line Side Number of Connections	1
Load Side Number of Connections	5
Thread Size 1 (TS1)	M5
Thread Size 2 (TS2)	M6
Dybde (D)	117mm
Height (H)	126 mm
Width (W)	150 mm
Unit Weight	0.68 kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

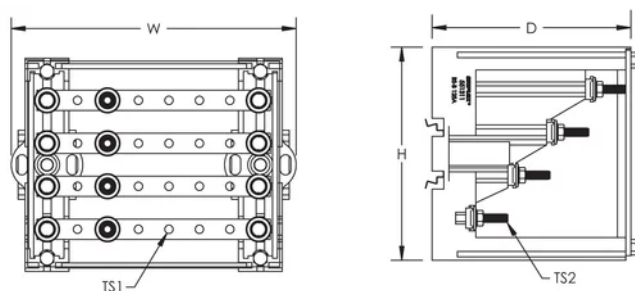

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE