

TR Four Pole Distribution Block, 250 A



CERTIFICERINGER



FUNKTIONER

Easily fixes onto asymmetric DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER


Katalognummer	TR-250A
Artikelnummer	563170
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass
Max Working Voltage, IEC (Ui)	630
Peak Short Circuit Current (Ipk)	34kA

Katalognummer	TR-250A
Short Term Withstand Current (Icw) 1s	17kA
Line Side Number of Connections	2
Load Side Number of Connections	4
Hole Size (HS)	8 mm
Thread Size (TS)	M6
Dybde (D)	68mm
Height (H)	150 mm
Width (W)	230 mm
Unit Weight	1.3 kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

DIAGRAMS

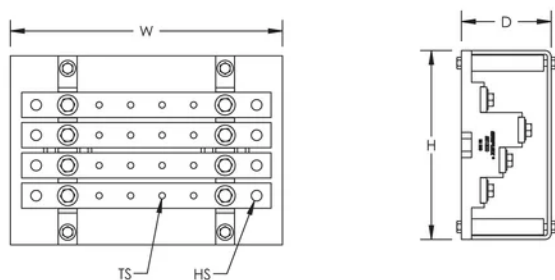

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE