

TRC Four Pole Distribution Block, 400 A



CERTIFICERINGER



FUNKTIONER

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER

Katalognummer	TRC-400A
Artikelnummer	563180
Materiale	Copper Glass Fibre Reinforced Polyamide Plexiglass
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	118kA
Short Term Withstand Current (Icw) 1s	28kA


Katalognummer	TRC-400A
Line Side Number of Connections	1
Load Side Number of Connections	10
Thread Size 1 (TS1)	M6
Thread Size 2 (TS2)	M10
Dybde (D)	50mm
Height (H)	338 - 390 mm
Width (W)	260 mm
A	290 mm
Unit Weight	2.65 kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

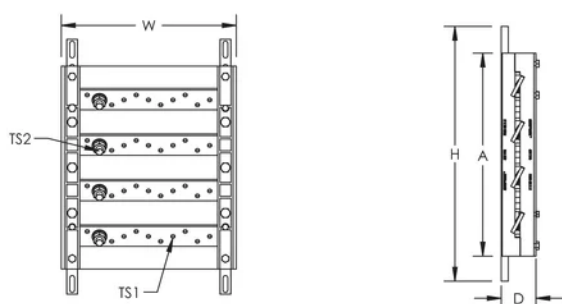

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE