


# TRC Four Pole Distribution Block, 630 A

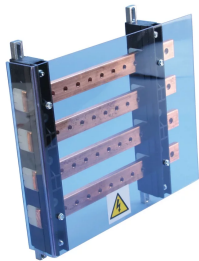

## CERTIFICERINGER



## FUNKTIONER

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

## SPECIFIKATIONER


| Katalognummer                         | TRC-630A                                                 |
|---------------------------------------|----------------------------------------------------------|
| Artikelnummer                         | 563190                                                   |
| Materiale                             | Copper<br>Glass Fibre Reinforced Polyamide<br>Plexiglass |
| Max Working Voltage, IEC (Ui)         | 1000                                                     |
| Peak Short Circuit Current (Ipk)      | 84kA                                                     |
| Short Term Withstand Current (Icw) 1s | 52kA                                                     |

|                                 |                                                                         |
|---------------------------------|-------------------------------------------------------------------------|
| <b>Katalognummer</b>            | <b>TRC-630A</b>                                                         |
| Line Side Number of Connections | 1                                                                       |
| Load Side Number of Connections | 8                                                                       |
| Hole Size (HS)                  | 10 mm                                                                   |
| Thread Size (TS)                | M8                                                                      |
| Dybde (D)                       | 60mm                                                                    |
| Height (H)                      | 338 - 390 mm                                                            |
| Width (W)                       | 340 mm                                                                  |
| A                               | 290 mm                                                                  |
| Unit Weight                     | 4.8 kg                                                                  |
| Flammability Rating             | UL® 94V-0                                                               |
| Complies With                   | IEC® 60439.1<br>IEC® 61439.1<br>IEC® 60695-2-11 (Glow Wire Test 960 °C) |

## YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

## DIAGRAMS

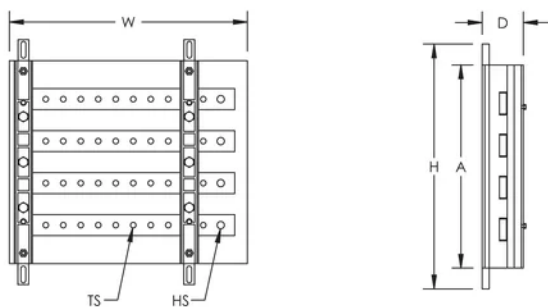

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**