


# TRS Four Pole Distribution Block, 160 A

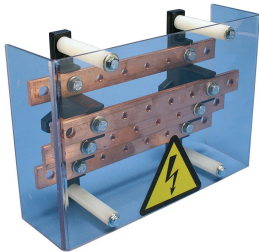

## CERTIFICERINGER



## FUNKTIONER

Easily fixes onto asymmetric DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

## SPECIFIKATIONER


| Katalognummer                    | TRS-160A                                                 |
|----------------------------------|----------------------------------------------------------|
| Artikelnummer                    | 563160                                                   |
| Materiale                        | Copper<br>Glass Fibre Reinforced Polyamide<br>Plexiglass |
| Max Working Voltage, IEC (Ui)    | 630                                                      |
| Peak Short Circuit Current (Ipk) | 34kA                                                     |

| Katalognummer                                      | TRS-160A                                                                |
|----------------------------------------------------|-------------------------------------------------------------------------|
| Short Term Withstand Current (I <sub>cw</sub> ) 1s | 13.2kA                                                                  |
| Line Side Number of Connections                    | 2                                                                       |
| Load Side Number of Connections                    | 4                                                                       |
| Hole Size (HS)                                     | 8 mm                                                                    |
| Thread Size (TS)                                   | M6                                                                      |
| Dybde (D)                                          | 68mm                                                                    |
| Height (H)                                         | 150 mm                                                                  |
| Width (W)                                          | 230 mm                                                                  |
| Unit Weight                                        | 1.15 kg                                                                 |
| Flammability Rating                                | UL® 94V-0                                                               |
| Complies With                                      | IEC® 60439.1<br>IEC® 61439.1<br>IEC® 60695-2-11 (Glow Wire Test 960 °C) |

## YDERLIGERE PRODUKTOPLYSNINGER

Line side and load side number of connections are per pole.

## DIAGRAMS

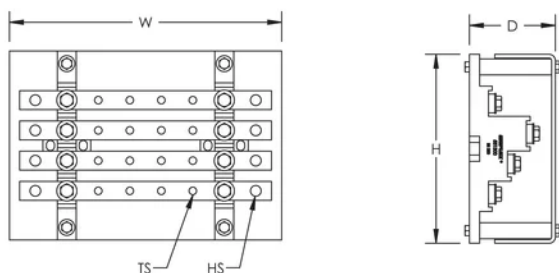

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**