

UFS nVent ERIFLEX Flexibar and IBSB Support Kit



CERTIFICERINGER



FUNKTIONER

Kit includes one rail and 24 retaining blocks

Create up to three 650 mm (25.6") supports capable of holding four nVent ERIFLEX Flexibar

Retaining blocks are halogen free

RoHS compliant

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Conductor Thickness	Conductor Width	Height (H)	Length (L)
UFS-KIT	553590	Aluminum, Polyamide	2 - 8 mm	15.5 - 120 mm	57.5 mm	2000mm

Table 2/2


Katalognummer	Artikelnummer	Width (W)	A	B	Unit Weight
---------------	---------------	-----------	---	---	-------------

UFS-KIT	553590	30 mm	24 mm	15 mm	2.3 kg
---------	--------	-------	-------	-------	--------

YDERLIGERE PRODUKTOPLYSNINGER

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

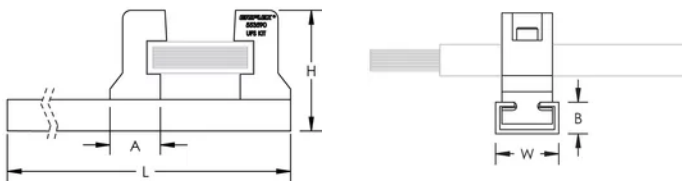

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE