


Universal Busbar Support

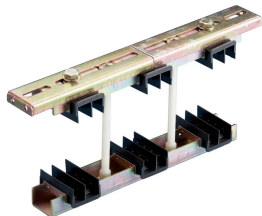

CERTIFICERINGER



FUNKTIONER

Universal fixing system

Installs quickly and easily

Extremely robust construction

Adjustable arms for easy mounting

Halogen free insulators

SPECIFIKATIONER

Max Working Voltage, IEC (Ui):	1000;1500
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C

Table 1/2


Katalognummer	Artikelnummer	Materiale	Typical Application Current Rating	Busbars per Phase	Busbar Width	Busbar Thickness
---------------	---------------	-----------	------------------------------------	-------------------	--------------	------------------

UBS4-5T	551020	Stål, Glass Fibre Reinforced Polyamide	3500 A	1 - 4	30 - 125 mm	5 mm
UBS2-10T	551080	Stål, Glass Fibre Reinforced Polyamide	3600 A	1 - 2	30 - 120 mm	10 mm

Table 2/2

Katalognummer	Artikelnummer	Width (W)	A	B	C	D
UBS4-5T	551020	375 - 575 mm	350 - 550 mm	176 mm	307 mm	110 mm
UBS2-10T	551080	375 - 575 mm	350 - 550 mm	176 mm	307 mm	110 mm

DIAGRAMS

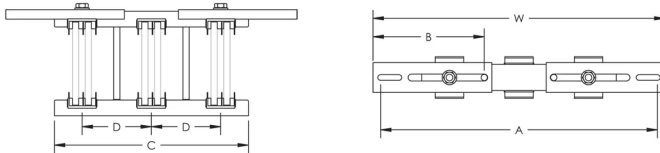

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE