

Universal Busbar Support, High Ampacity



CERTIFICERINGER



FUNKTIONER

Universal fixing system

Installs quickly and easily

Extremely robust construction

Screws are made from non-magnetic stainless steel

Halogen free insulators

SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Max Working Voltage, IEC (Ui)	Working Temperature	Complies With	Flammability Rating
UBS2-10T-160	561520	Stål, Glass Fibre Reinforced Polyamide, Stainless Stål 304 (EN 1.4301)	1000, 1500	-40 to 130 °C	IEC® 60439.1, IEC® 61439.1, IEC® 60695-2-11 (Glow Wire Test 960 °C)	UL® 94V-0


Table 2/3

Katalognummer	Artikelnummer	Typical Application Current Rating	Busbars per Phase	Busbar Width	Busbar Thickness	Width (W)
UBS2-10T-160	561520	5700 A	1 - 2	160 mm	10 mm	307 mm

Table 3/3

Katalognummer	Artikelnummer	A
UBS2-10T-160	561520	110 mm

DIAGRAMS

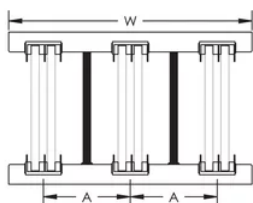

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE